

WORKSHOP[®] MD

WET/DRY VACS

3

SPEED

1625

CFM
2200 MAX

- **Efficient Motor Technology Results In Low Current Draw With Maximum Air Flow**
- **Low Amp Draw Allows Use Of Multiple Units On A Single Circuit**
- **Isolation Motor Mounts Reduce Vibration And Motor Noise**
- **Stackable For Storage And Transport**
- **Dries Carpets And Subfloors Quickly**
- **30' Power Cord For Added Convenience**
- **Efficient Guard Is Designed To Disperse Air Over Larger Drying Area**
- **Exhaust Flange Allows For Easily Attaching Carpet Clamps And Collapsible Ducting**
- **Large Carry Handle, Collapsible Handle And Wheels All Make Transporting Quick And Easy**
- **Multiple Drying Positions For Added Versatility**

Featuring three speed choices, the Air Mover provides high volume air circulation to dry wet carpets, floors, entrances, etc.

AIR MOVER



Includes: Air Mover, Owner's Manual

WSI625AM

5 YEAR
LIMITED
WARRANTY

WORKSHOP[®] MD

WET/DRY VACS

www.WORKSHOPvacs.com

3

SPEED

1625

CFM
2200 MAX

SPECIFICATIONS

Motor:	0.4 HP, 3 Speed
Voltage:	120
Amps:	Hi-3.0 / Med-2.7 / Lo-2.2
CFM:	1,625 (2200 MAX)
Drying Positions:	Three - 0° / 60° / 90°
Cord Length:	30' / 9 m
Construction:	Polypropylene
Weight:	29 Lbs / 13,2 Kg
U.L. Listed:	Yes

30'/9M

Large handle makes it easier to carry.

Collapsible handle and wheels allow for easily transport of 1 or 2 units.

Convenient cord wrap.

Efficient housing design/motor maximizes airflow with minimal current draw.


Exhaust flange to easily attach carpet clamps, collapsible ducting, etc.

High volume air movement delivers the desired amount of air movement for cooling, carpet drying, restoration, etc.

Efficient guard design allows air to be spread over larger area.



Stackable for storage or transport up to two units high

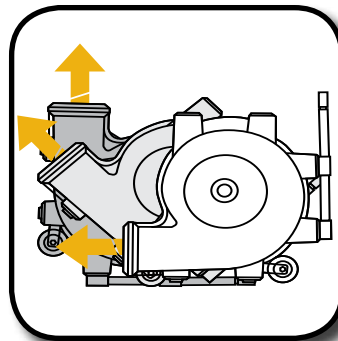

WORKSHOP[®] Wet/Dry Vacs
St. Louis, MO

WORKSHOPbrand



All details subject to change without notice.
See website for details on warranty.